


High Density Cabinet Power Distribution Unit (CDU) Solutions for Data Centers

7-12 kW per CDU

Model	Voltage/Current	Outlets
C-12HD2	208V/ 20 or 30A	(12) C19
C-21VD/VY	3-Phase 208V/ 20A	(21) C13
C-24VD1	120V/ 20 or 30A	(24) 5-20R
C-24VD2	208V/ 20 or 30A	(24) C13
C-24VD/VY	3-Phase 208V/30A	(24) C13
C-24VD/VY-MA	3-Phase 208V/ 30A	(18) C13+(6) C19
C-48VD1	120V/ 20 or 30A	(48) 5-20R
C-48VD2	208V/ 20 or 30A	(48) C13
CS-3AVY	3-Phase 208V/ 20 or 30A	(30) 5-20/C13/C19
CS-3VD/DY	3-Phase 208V/ 30A	C13 + C19
CS-12HD2	208V/ 20 or 30A	(12) C19
CS-21VD/VY	3-Phase 208V/ 20A	(21) C13
CS-24VD/VY	3-Phase 208V/ 30A	(24) C13
CS-24VD/VY-MA	3-Phase 208V/ 30A	(18) C13+(6) C19
CS-27VY	3-Phase 208V/ 30A	(6) 5-20R+(21) C13
CS-36VD/VY	3-Phase 208V/ 30A	(36) C13
CS-48VD1	120V/ 20 or 30A	(48) 5-20R
CS-48VD2	208V/ 20 or 30A	(48) C13
CW-24VD/VY	3-Phase 208V/ 20 or 30A	(24) C13
CW-24VD/VY-A1	3-Phase 208V/ 30A	(18) C13 + (6) C19
CW-24V2-A1	208V/ 30A	(18) C13 + (6) C19
CW-32VD1	120V / 20 or 30A	(32) 5-20R
CW-32VD2	208V/ 20 or 30A	(32) C13
CW-48VD/VY	3-Phase 208V/ 20 or 30A	(48) C13
CWG-24VD/VY	3-Phase 208V/ 30A	(18) C13+(6) C19

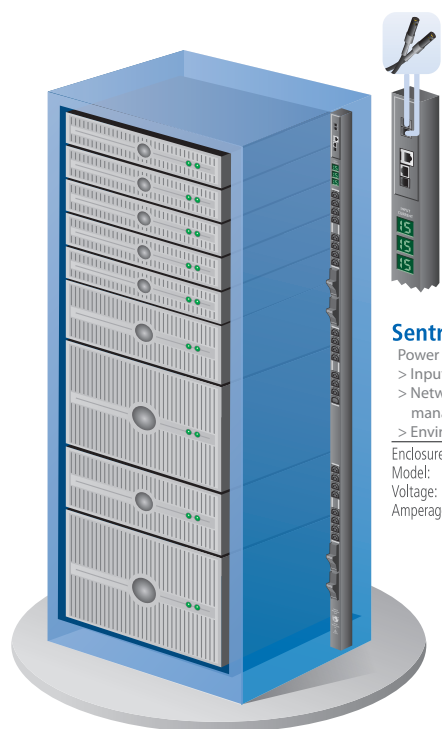

Sentry: Switched CDU
 Power Distribution with:
 > Input Current Monitor LED
 > Network based power management
 > Environmental Monitoring

Enclosure: Zero-U Vertical
 Model: CW-24VD/VY
 Voltage: 3-Phase 208V
 Amperage: 20A / 30A

12-22 kW per CDU

Model	Voltage/Current	Outlets
C-12HD2	208V/ 20 or 30A	(12) C19
C-12HDD/HDY	3-Phase 208V/ 20 or 30A	(12) C19
C-48VD2	208V/ 20 or 30A	(48) C13
C-48VDY	3-Phase 208V/30A	(48) C13
CS-3VD/DY	3-Phase 208V/ 60A	C13 + C19
CS-12VD/VY	3-Phase 208V/ 60A	(12) C19
CS-12HDD/HDY	3-Phase 208V/ 20 or 30A	(12) C19
CS-18V	3-Phase 208V/ 60A	(6) C13+(12) C19
CS-36VD/VY-A4	3-Phase 208V/ 60A	(24) C13+(12) C19
CS-48VDD/VDY	3-Phase 208V/ 20 or 30A	(48) C13
CS-54VDY	3-Phase 208V/ 20 or 30A	(12) 5-20R +(42) C13
CS-84V2	208V/ 30A	(84) C13
CS-84VDD/VDY	3-Phase 208V/ 20 or 30A	(84) C13
CW-24VDX/VY-A1	3-Phase 208V/ 60A	(18) C13+(6) C19
CW-32VD2	208V/ 30A	(32) C13



Sentry: Smart CDU
 Power Distribution with:
 > Input Current Monitor LED
 > Remote Access via IP
 > Environmental Monitoring

Enclosure: Zero-U Vertical
 Model: CS-48VDD/VDY
 Voltage: 3-Phase 208V
 Amperage: 20A / 30A



Sentry: Metered CDU
Power Distribution with:
> Input Current Monitor LED

Enclosure: Zero-U Vertical
Model: C-12V1
Voltage: 100-120V
Amperage: 20A / 30A

2-4 kW per CDU

Model	Voltage/Current	Outlets
C-10H1	120V/20 or 30A	(10) 5-20R
C-12V1	120V/20 or 30A	(12) 5-20R
C-24V1	120V/20 or 30A	(24) 5-20R
CS-16V1-MX	120V/20A	(16) 5-20R
CS-16V1	120V/20 or 30A	(16) 5-20R
CS-24V1	120V/20 or 30A	(24) 5-20R
CW-2H1	120V/20A	(2) 5-20R
CW-8H1	120V/20 or 30A	(8) 5-20R
CW-16V1	120V/20 or 30A	(16) 5-20R
CW-16V1-MX	120V/20A	(16) 5-20R

4-6 kW per CDU

Model	Voltage/Current	Outlets
C-4H2	208V/ 20 or 30A	(4) C19
C-12H2	208V/ 20 or 30A	(12) C13
C-12V2	208V/ 20 or 30A	(12) C13
C-24V2	208V/ 20 or 30A	(24) C13
C-24VD1	120V/ 20 or 30A	(24) 5-20R
C-24H2	208V/ 30A	(24) C13
C-24V2-A	208V/ 20 or 30A	(18) C13 + (6) C19
C-48VD1	120V/ 20 or 30A	(48) 5-20R
CS-16V2-MX	208V/ 20A	(16) C13
CS-16V2	208A/ 20 or 30A	(16) C13
CS-24V2	208V/ 20 or 30A	(24) C13
CS-24V2-MA	208V/ 20 or 30A	(18) C13 + (6) C19
CS-48VD1	120V/ 20 or 30A	(48) 5-20R
CW-2H2	208V/ 20A	(2) C13
CW-8H2	208V/ 20 or 30A	(8) C13
CW-16V2	208V/ 20 or 30A	(16) C13
CW-16V2-MX	208V/ 20A	(16) C13
CW-24V2	208V/ 20 or 30A	(24) C13
CW-32VD1	120V/ 20 or 30A	(32) 5-20R
CWG-16V2	208V/ 20 or 30A	(12) C13 + (4) C19



Sentry: Switched CDU
Power Distribution with:
> Input Current Monitor LED
> Remote Access & Reboot via IP
> Environmental Monitoring

Enclosure: Zero-U Vertical
Model: CW-16V2
Voltage: 208V
Amperage: 20A / 30A

Legend

- Metered- Input Current Monitor LED
- Smart- Input Current Monitor, Remote Access via IP, Environmental Monitoring
- Switched- Input Current Monitor, Remote Access and Reboot via IP, Environmental Monitoring
- POPS (Per Outlet Power Sensing), Input Current Monitor, Remote Access and Reboot via IP, Environmental Monitoring



Server Technology

HEADQUARTERS - NORTH AMERICA
Server Technology, Inc.
1040 Sandhill Drive
Reno, NV 89521
United States
1.775.284.2000 Tel
1.775.284.2065 Fax
sales@servertech.com
www.servertech.com
www.servertechblog.com

EMEA
Server Technology Intl
Sienna Court
The Broadway
Maidenhead
Berkshire
SL6 1NJ
United Kingdom
+44 (0) 1628 509053 Tel
+44 (0) 1628 509100 Fax
salesint@servertech.com

APAC
Server Technology Intl
37th Floor, Singapore Land Tower
50 Raffles Place
Singapore 048623
+65 (0) 6829 7008 Tel
+65 (0) 6234 4574 Fax
salesint@servertech.com