

# How do I quickly configure IP addresses for my rack PDUs?

APPLICATION NOTE ACC-003 | August 2015

## Learn how StartUp Stick™ increases the speed of Server Technology CDU® deployment.




### Typical Application

I prefer not to use DHCP for infrastructure pieces like the rack PDU. I have been writing scripts and walking around with my laptop on a crash-cart to connect to each PDU, login, and run the script. This is a tedious process that I would like to avoid.

How can I speed up this process for getting the rack PDU on the network to begin monitoring and management of the equipment I run the business on?

### Our Solution

The StartUp Stick by Server Technology provides a unique means to more easily create individual CDU configurations, including IP addresses, on a computer workstation and be able to mass deploy these configurations to each CDU in mere seconds. You get a spreadsheet-based tool with built-in rules verification, a standard USB interface for PC and MAC, simple LED pass/fail indicator, and on-board logging.

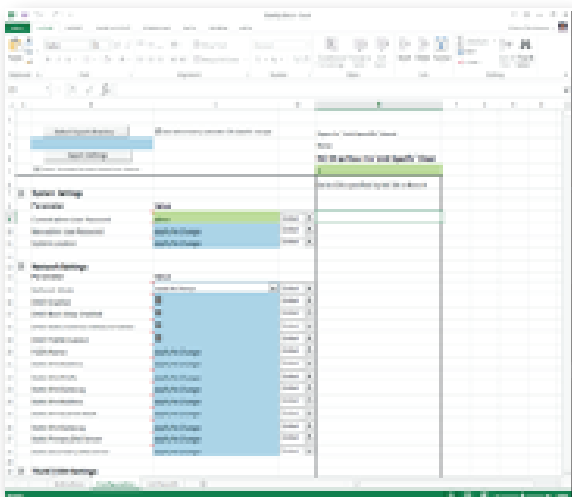

# Get online with StartUp Stick

## We have the solutions you need for reducing time to deploy.

Whether or not you can use DHCP for IP configuration, we have a solution to fit your rack/cabinet PDU (CDU) network deployment needs. In addition to DHCP enabling by default, Server Technology CDUs provide for quick deployment with the StartUp Stick. Once on the network, further configuration can be completed en masse through the use of the Sentry Power Manager (SPM) SNAP feature.

### Key CDU Accessories:

- > StartUp Stick configuration tool
- > SPM energy management system
- > EZip™ secure-cable solution
- > ST Eye Bluetooth monitoring
- > EMTH temperature/humidity probes and EMCU for leak detection and closed contact monitoring

### Key Intelligent CDU Benefits:

- > PIPS® and/or POPS® high-accuracy measurements of current, voltage, energy, and other key power metrics
- > Linked expansion CDU for reduced network port requirements
- > Outlet control
- > Extensive security
- > SNMP traps and email alerts



**Server Technology**  
Quality Rack Power Solutions



Stay Powered



Be Supported



Get Ahead

#### HEADQUARTERS NORTH AMERICA

Server Technology  
1040 Sandhill Drive  
Reno, NV 89521  
United States  
Tel: +1.775.284.2000  
Fax: +1.775.284.2065  
sales@servertech.com  
www.servertech.com  
www.servertechblog.com

#### WESTERN EUROPE, MIDDLE EAST & AFRICA

Server Technology  
Fountain Court  
2 Victoria Square  
Victoria Street  
St. Albans, AL1 3TF  
United Kingdom  
Tel: +44 (0) 1727 884676  
Fax: +44 (0) 1727 220815  
salesint@servertech.com

#### CENTRAL EUROPE, EASTERN EUROPE & RUSSIA NIEDERLASSUNG DEUTSCHLAND

Server Technology  
42119 Wuppertal  
Germany  
Tel: +49 202 693917 x0  
Fax: +49 202 693917-10  
salesint@servertech.com

#### APAC

Server Technology  
Room 2301, 23/F, Future Plaza  
111-113 How Ming Street,  
Kwun Tong, Hong Kong  
Tel: +852 3916 2048  
Fax: +852 3916 2002  
salesint@servertech.com